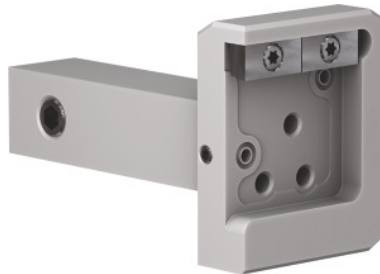


**Garant**
**Vario plus eco toolholder cranked 90°, left-hand, Shank width b: 25mm**

**Order data**

|              |               |
|--------------|---------------|
| Order number | 274503 25     |
| GTIN         | 4067263120513 |
| Item class   | 21U           |

**Description**
**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

**Suitable for:**

Vario plus eco blade carriers No. 274512; 274514; 274516; 274518; 274520; 274522; 274540.

**Supplied with:**

Including assembly screws.

**Note:**

Coolant transfer only possible in conjunction with GARANT Master eco toolholders No. 317906 – 319136. Optional connection possibility via hose connection (G1/8 inch) No. 269207 and 269208.

**Technical description**

|                  |          |
|------------------|----------|
| L <sub>2</sub>   | 16 mm    |
| Overall length L | 100 mm   |
| Assembly bolt    | 279815 9 |
| Shank width b    | 25 mm    |
| L <sub>1</sub>   | 54 mm    |
| Series           | Eco      |

|                  |            |
|------------------|------------|
| Application type | left-hand  |
| Through-coolant  | yes        |
| Type of product  | Toolholder |