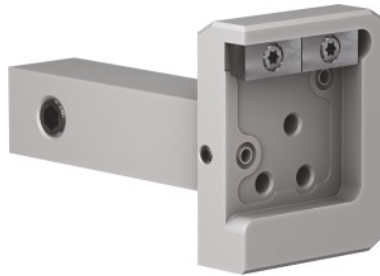


Garant**Vario plus eco toolholder cranked 90°, left-hand, Shank width b: 20mm****Order data**

Order number	274503 20
GTIN	4067263133056
Item class	21U

Description**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Vario plus eco blade carriers No. 274510; 274512; 274514; 274516; 274518; 274520; 274522; 274540.

Supplied with:

Including assembly screws.

Note:

Coolant transfer only possible in conjunction with GARANT Master eco toolholders No. 317906 – 319136. Optional connection possibility via hose connection (G1/8 inch) No. 269207 and 269208.

Technical description

L ₁	54 mm
Shank width b	20 mm
Assembly bolt	279815 9
L ₂	16 mm
Overall length L	85 mm
Series	Eco

Application type	left-hand
Through-coolant	yes
Type of product	Toolholder