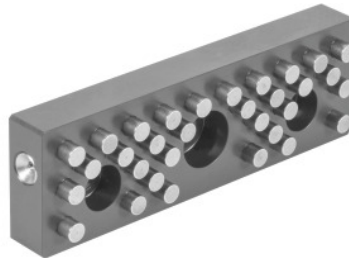


**Garant**
**Jaw with positioning pins, for jaw width: 125mm**

**Order data**

Order number	362624 125
GTIN	4067263092186
Item class	31S

**Description**
**Version:**

- **Hardened steel, Tenifer gas nitrided (tolerance  $\pm 0.01$  mm).**
- **Simple to fit on the vice.**
- **Pins pushed in mechanically.**
- **Compressed air operation via valves on both sides.**
- **The fixed and movable jaws are identical.**
- **Requires a 5.5 bar compressed air supply**

**Application:**

Quick changeover for different machining operations.

- **Quick and fully repeatable positioning accuracy.**
- **Eliminates tedious fitting of jaw inserts.**

**Suitable for:**

**ALLMATIC** NC8 125, HD 125, TC, TITAN2 125.

**BULL** pneumatic 125, mechanical 125.

**KESEL** ARNO125, CNC125, NCA125.

**RÖHM** RKE125, RKE-L125, RKE-U125, RKG-L125, RKE-LV125.

**Technical description**

Type of product	Vice jaws
-----------------	-----------

