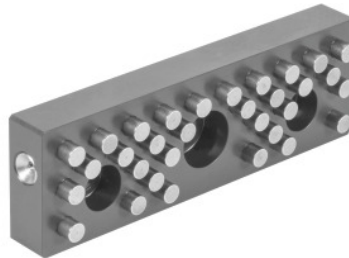


Garant**Jaw with positioning pins, for jaw width: 160mm****Order data**

Order number	362624 160
GTIN	4067263092193
Item class	31S

Description**Version:**

- **Hardened steel, Tenifer gas nitrided (tolerance ± 0.01 mm).**
- **Simple to fit on the vice.**
- **Pins pushed in mechanically.**
- **Compressed air operation via valves on both sides.**
- **The fixed and movable jaws are identical.**
- **Requires a 5.5 bar compressed air supply**

Application:

Quick changeover for different machining operations.

- **Quick and fully repeatable positioning accuracy.**
- **Eliminates tedious fitting of jaw inserts.**

Suitable for:

ALLMATIC NC8 160, HD 160, TC, TITAN2 160.

BULL pneumatic 160, mechanical 160.

KESEL ARNO160, CNC160, NCA160.

RÖHM RKE160, RKE-L160, RKE-U160, RKG-L160, RKE-LV160.

Technical description

Type of product	Vice jaws
-----------------	-----------

