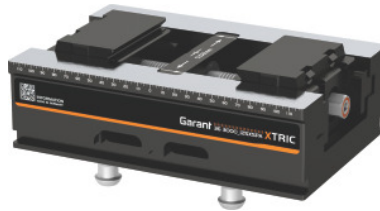


**Garant**
**Centring vice basic device Xtric, Type: 125XSPA**

**Order data**

Order number	363000 125XSPA
GTIN	4067263101109
Item class	310

**Description**
**Version:**

- **Very good accessibility and perfectly symmetrical.**
- **Fully hardened and precision milled on the underside.**
- **Clamps raw materials and finished parts with the least possible backstroke of the jaws / component.**
- **Central alignment delivers perfectly centred clamping.**
- **The clamping range can be changed by reversing the jaws.**

**Application:**

Perfect for 5-face machining. Centred clamping.

**Suitable for:**

Top jaws No. 363010 – 363045.

**Supplied with:**

Base body, spindle, spindle nuts and four clamping studs suitable for automation extension base No. 360164 XP80Z.

**Optional extras:**

Torque wrench No. 656050, socket No. 642229 13, assembly station No. 358595 80.

**Note:**

Suitable for the GARANT TurnTable automation system in combination with / for automation extension base No. 360164 XP80Z. Suitable top jaws No. 363010 – 363045 are not included in the scope of supply. Clamping situation S2 arises by reversing the jaws.

**Technical description**

L	186 mm
B	125 mm
Colour code	Xtric 125
Weight	10.6 kg
Height H	54 mm
Width across flats	13 mm
Width across flats	5 mm
maximum clamping force	32 kN
maximum torque	132 Nm
Version	Zero-point clamping system
Reference dimension	80 mm
Type of product	Machine vice