


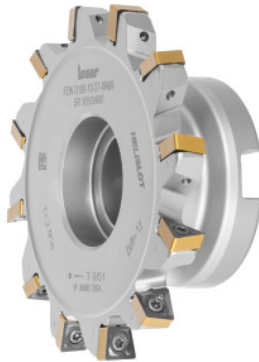

HELISLOT side milling cutter with flange, \varnothing DC / Zeff: 160/18mm



Order data

Order number	227720 160/18
GTIN	7291075430882
Item class	19D

Description

Version:

Economical machining of grooves and T-slots. Achieve different slot widths with only one insert size thanks to the insert seat concept with staggered teeth formation. Square inserts with positive rake angle for efficient and gentle machining. Very reliable process thanks to optimised insert support in the seat.

Spare part:

Pack of insert screws No. **229695 3** (TX9; 2.0 Nm).

Technical description

Series	HELISLOT
Cutting edge \varnothing D _C	160 mm
Number of indexable inserts	18
Overall length L _{tot}	50 mm
Number of effective inserts Z _{eff}	18
Collar length L ₁	35 mm

maximum cutting depth $a_{e\max}$	45 mm
Mounting bore \varnothing	40 mm
Slot width a_p	10 mm
Manufacturer's designation	FDN D160-10-40-XN09
Shank type	with bore
Type of product	Side milling cutter

Accessories

Set of insert screws 5 pieces Type 3	229695 3
--------------------------------------	----------