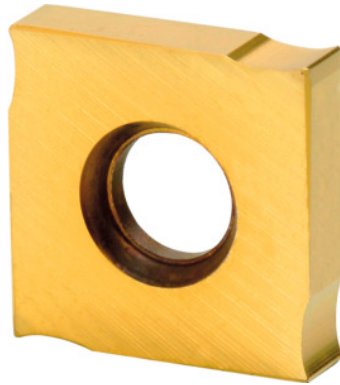


**Garant****SNHX 1103 neutral, Type: ST900****Order data**

|              |               |
|--------------|---------------|
| Order number | 218581 ST900  |
| GTIN         | 4045197656346 |
| Item class   | 21A           |

**Description****Note:**Standard application values for  $a_e$  max.for slot width  $a_p$ : 5 mm

Grade: HB7525

Feed  $f_z$  per tooth: 0.08 mm

Chamfer width: 0.15 mm

**Technical description**

|                           |           |
|---------------------------|-----------|
| Feed $f_z$ per tooth      | 0.08 mm   |
| Type                      | ST900     |
| Chamfer width             | 0.15 mm   |
| Grade                     | HB7525    |
| ISO code indexable insert | SNHX 1103 |
| Tool material             | Carbide   |

|                           |                              |
|---------------------------|------------------------------|
| Insert thickness          | 2.7 mm                       |
| for slot width $a_p$      | 5 mm                         |
| Number of changes/inserts | 4                            |
| Type of product           | Indexable insert for milling |