


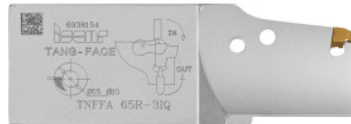

## TANGGRIP TNFFA-IQ axial grooving toolholder reinforced, right-hand, Ø range / cut DAXN-DAXX: 60-80mm



### Order data

Order number	274202 60-80
GTIN	7291075311006
Item class	26D

### Description

#### Application:

For face grooving.

#### Suitable for:

Cutting inserts No. 274422 – 274226.

#### Attention:

Please order the assembly key No. 279952 separately.

### Technical description

Overall length L	90 mm
Series	TANG-GRIP
Grooving depth $t_{max}$	27 mm
Groove width w	4 mm
WF	9 mm
WB_2	18 mm
Functional height $h_1$	24.8 mm
Shank height $h_5$	32 mm
Manufacturer's designation	TNFFA 60R-4IQ
Overhang	27 mm

Application type	right-hand
Through-coolant	no
axial grooving possible	yes
Type of product	Toolholder