


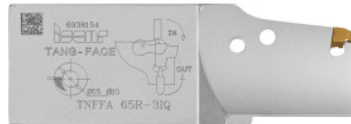

TANGGRIP TNFFA-IQ axial grooving toolholder reinforced, left-hand, Ø range / cut DAXN-DAXX: 80-100mm



Order data

| | |
|--------------|---------------|
| Order number | 274203 80-100 |
| GTIN | 7291075310948 |
| Item class | 26D |

Description

Application:

For face grooving.

Suitable for:

Cutting inserts No. 274422 – 274226.

Attention:

Please order the assembly key No. 279952 separately.

Technical description

| | |
|----------------------------|---------------|
| Groove width w | 3 mm |
| Grooving depth t_{max} | 27 mm |
| Series | TANG-GRIP |
| Overall length L | 90 mm |
| WB_2 | 16.7 mm |
| WF | 9.5 mm |
| Shank height h_s | 32 mm |
| Functional height h_1 | 24.8 mm |
| Manufacturer's designation | TNFFA 80L-3IQ |
| Overhang | 27 mm |

| | |
|-------------------------|------------|
| Application type | left-hand |
| Through-coolant | no |
| axial grooving possible | yes |
| Type of product | Toolholder |