


# Yale

## Hydraulic lifting wedge HK-16T, Safe working load/Type: 16/KIT t

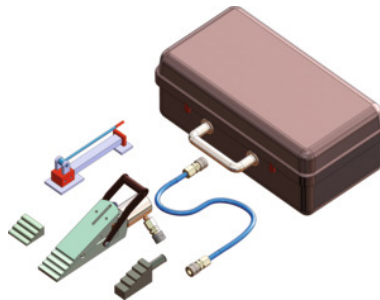

### Order data

Order number	086048 16/KIT
GTIN	4053981522463
Item class	08Y

### Description

#### Version:

All components and attachments satisfy **metric standard ranges**, which considerably simplifies assembly, service, and the procurement of spare parts. **100 % compatibility** with all commercially-available 700 bar hydraulic systems.

Forged lifting wedge with parallel opening stroke and a **very small insertion gap of only 9.5 mm** for connection to a hydraulic system with max. 700 bar operating pressure. Ready-to-use set in a **carrying case** with one **lifting wedge** size 16/1, one 700 bar **2-stage hydraulic hand pump**, one 700 bar **hydraulic hose**, one **safety block**, and one **stepped block**.

#### Application:

For vertical lifting of heavy objects, equipment, and machinery. Maximum lifting force per lifting wedge is 16 t, several lifting wedges can be used if required.

#### Note:

**Closed systems are pre-mounted ex works, filled and air bled.**

For hydraulic hand pump see No. 086050, hydraulic hose No. 086081, pressure gauge No. 086087.

Weight: 9 kg

### Technical description

maximum lifting force	16 t
-----------------------	------

Weight	9 kg
very small access gap	9.5 mm
Type	KIT