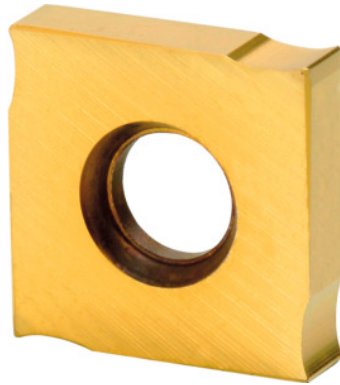


Garant**SNHX 1207 neutral, Type: ST900****Order data**

Order number	218621 ST900
GTIN	4045197532190
Item class	21A

Description**Note:**

Standard application values for a_e max.

for slot width a_p : 12; 16 mm

Grade: HB7525

Feed f_z per tooth: 0.08 mm

Chamfer width: 0.25 mm

Technical description

Feed f_z per tooth	0.08 mm
Type	ST900
Chamfer width	0.25 mm
Grade	HB7525
ISO code indexable insert	SNHX 1207
Tool material	Carbide

Insert thickness	7 mm
for slot width a_p	12; 16 mm
Number of changes/inserts	4
Type of product	Indexable insert for milling