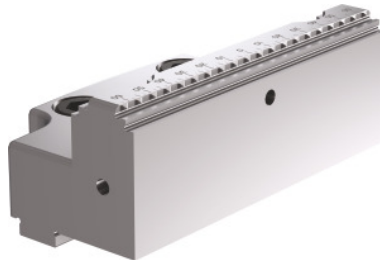


Garant**Universal top jaw for Xpent, for jaw width b: 125mm****Order data**

Order number	361138 125
GTIN	4067263109136
Item class	310

Description**Version:**

Clamping steps with a height of 3 mm and 3 mm contact area. With gripp step and smooth clamping step. Hardened and ground. Fastening screws.

Application:

To quickly extend the capacity of the Xpent No. 361100 size 1-2

Material:

Hardened steel.

Suitable for:

Xpent No. 361100 size 1-2

Note:

If this jaw is used, the clamping range can be extended by 108 mm without needing to rotate the pillars. When using a rotated Universal top jaw No. 361138, the fixed jaw of the Xpent No. 361100 can only be released using plug-in head No. 361139.

Technical description

Jaw length l	68 mm
Jaw height h	45 mm
suitable for colour code	Xpent1-2
Type of product	Vice jaws

