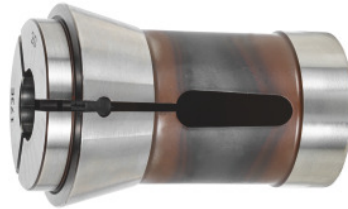


**Push-out collet, round, to DIN 6343, 173 E, Clamping \varnothing : 9mm****Order data**

Order number	329560 9
GTIN	4067263110781
Item class	32Z

Description**Version:**

Collets, **round profile in 1 mm increments. Please specify required clamping \varnothing with order.**

Standard:

DIN 6343

Accuracy:

Concentricity tolerances: D = 1 to 10 mm = 0.02 mm D = 10 to 30 mm = 0.03 mm D = 30 to 60 mm = 0.04 mm

Note:

Other diameters and profiles (e.g. square or hexagon) **on request!**

Profile \varnothing 1.0 – 8.0 mm smooth. From \varnothing 8.5 mm with transverse serrations.

Technical description

K	60 mm
F	48 mm
Angle α	17.5 degrees
Overall length L	94 mm
A	50 mm
Type	173 E

Type of product

Collet