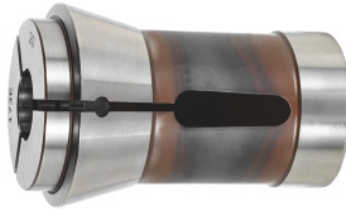


**Push-out collet, round, to DIN 6343, 173 E, Clamping \varnothing : 14mm****Order data**

| | |
|--------------|---------------|
| Order number | 329560 14 |
| GTIN | 4067263115236 |
| Item class | 32Z |

Description**Version:**

Collets, **round profile in 1 mm increments. Please specify required clamping \varnothing with order.**

Standard:

DIN 6343

Accuracy:

Concentricity tolerances: D = 1 to 10 mm = 0.02 mm D = 10 to 30 mm = 0.03 mm D = 30 to 60 mm = 0.04 mm

Note:

Other diameters and profiles (e.g. square or hexagon) **on request!**

Profile \varnothing 1.0 – 8.0 mm smooth. From \varnothing 8.5 mm with transverse serrations.

Technical description

| | |
|------------------|--------------|
| A | 50 mm |
| Angle α | 17.5 degrees |
| F | 48 mm |
| Overall length L | 94 mm |
| K | 60 mm |
| Type | 173 E |

Type of product

Collet