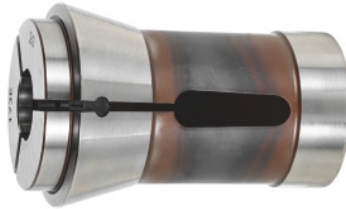


**Push-out collet, round, to DIN 6343, 173 E, Clamping  $\varnothing$ : 28mm****Order data**

Order number	329560 28
GTIN	4067263115373
Item class	32Z

**Description****Version:**

Collets, **round profile in 1 mm increments. Please specify required clamping  $\varnothing$  with order.**

**Standard:**

**DIN 6343**

**Accuracy:**

**Concentricity tolerances:** D = 1 to 10 mm = 0.02 mm D = 10 to 30 mm = 0.03 mm D = 30 to 60 mm = 0.04 mm

**Note:**

Other diameters and profiles (e.g. square or hexagon) **on request!**

Profile  $\varnothing$  1.0 – 8.0 mm smooth. From  $\varnothing$  8.5 mm with transverse serrations.

**Technical description**

Angle $\alpha$	17.5 degrees
K	60 mm
F	48 mm
A	50 mm
Overall length L	94 mm
Type	173 E

Type of product

Collet