




## Push-out collet, round, to DIN 6343, 185 E, Clamping $\varnothing$ : 55mm

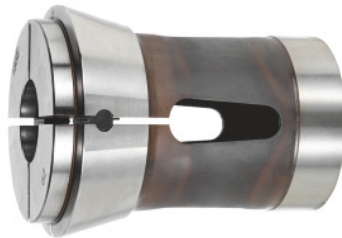

### Order data

|              |               |
|--------------|---------------|
| Order number | 329565 55     |
| GTIN         | 4067263116035 |
| Item class   | 32Z           |

### Description

#### Version:

Collets, **round profile in 1 mm increments. Please specify required clamping  $\varnothing$  with order.**

#### Standard:

**DIN 6343**

#### Accuracy:

**Concentricity tolerances:** D = 1 to 10 mm = 0.02 mm D = 10 to 30 mm = 0.03 mm D = 30 to 60 mm = 0.04 mm

#### Note:

Other diameters and profiles (e.g. square or hexagon) **on request!**

Profile  $\varnothing$  4.0 – 8.0 mm smooth. From  $\varnothing$  9.0 mm with transverse serrations.

### Technical description

|                  |            |
|------------------|------------|
| Angle $\alpha$   | 20 degrees |
| A                | 73 mm      |
| Overall length L | 110 mm     |
| K                | 84 mm      |
| F                | 66 mm      |
| Type             | 185 E      |

Type of product

Collet