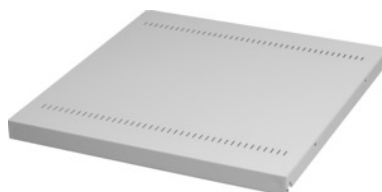


Garant GRIDLINE

Storage shelf slotted, Front height: 25mm**Order data**

Order number	935161 25
GTIN	4067263130048
Item class	9GK

Description**Version:**

Made of sheet metal with cross-bracing on the underside. Standard storage shelf for insertion.

Load capacity 150 kg.**Colour:**

Light grey RAL 7035, powder-coated.

Note:

- **The storage shelf also acts as the locking base in combination with the central locking No. 935590, 935595. Prepared for mounting cylinder locks in the fascia.**
- **25 mm high storage shelves cannot be combined with intermediate bridging rails and end rails.**

Technical description

Application range	Drawer/shelf combination unit
Shelf load capacity / maximum distributed shelf load (on metal)	150 kg
Front height	25 mm
Storage shelf version	fixed shelf
Storage shelf version	straight shelf
Storage shelf version	slotted shelf
Material thickness	1.2 mm

Data sheet

Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003
Width	1453 mm
Depth	675 mm
Width in G	56
Depth in G	24
Type of product	Storage shelf