


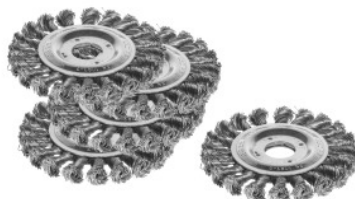

Value pack wheel brush steel wire 0,50 mm, Brush $\varnothing D_1 \times$ bore $\varnothing d_1$ / thread M: 115X22mm



Order data

Order number	GG5712 115X22
GTIN	4067263136194
Item class	GGN

Description

Version:

Straight wheel brush with smooth wire 0.50 mm, **knotted** and firmly crimped into the steel body. **Very aggressive brushing effect with high wear resistance.**

Corresponds to No. 571203.

Application:

For heavy brush work, e.g. descaling, removing rust, removing paint, roughening, cleaning metal parts, also for cleaning formwork boards.

Left knotted, reliably avoids premature unwinding.

Technical description

Number of twisted knots	20
Brush $\varnothing D_1$	115 mm
Length of brush section H_1	24 mm
Bore $\varnothing d_1$	22 mm
maximum speed	12500 min ⁻¹
Bristle thickness	0.5 mm
Bristle width L_1	14 mm

Brush material	Steel wire
Type of product	Wheel brush

Accessories

Wheel brush Steel wire 0.50 mm Brush \varnothing D1 x bore \varnothing d1 / thread M 115X22 mm	571203 115X22
--	---------------