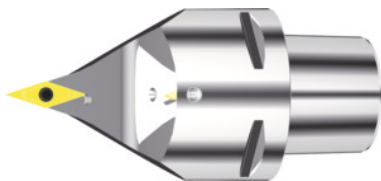


Boring bar neutral, PSC, Shank Ø / insert size – A dimension: 6316-130HPmm**Order data**

Order number	320381 6316-130HP
GTIN	4070445097978
Item class	36D

Description**Note:**

Order the suitable **HP nozzle** No. 320001 separately. Spare parts No.320610 – 320626 can be found in the spare parts list.

PSC clamping stud on request.

Technical description

Shank Ø	63 mm
Insert size	16
Overhang dimension A	130 mm
suitable indexable insert	VC.. 1604..
Spare part	S07
Adapter	PSC
Application type	neutral
Arbor standard	ISO 26623-1
Through-coolant	yes
Type of product	Boring bar