




## Stepped jaws fixed, Type: 125

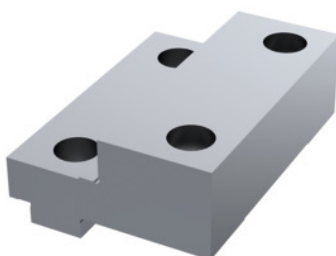

### Order data

|              |               |
|--------------|---------------|
| Order number | 360574 125    |
| GTIN         | 4069515011303 |
| Item class   | 32P           |

### Description

**Version:**

Hardened and ground parallel jaws.

**Application:**

For fitting front jaws No. 360538; 360539; 360541.

**Material:**

Hardened, nitrided, both sides smooth.

**Suitable for:**

NC high pressure vice No. 360565.

**Supplied with:**

Incl. fastening screws.

### Technical description

|                          |          |
|--------------------------|----------|
| Jaw length l             | 92 mm    |
| Height h <sub>1</sub>    | 20 mm    |
| Length l <sub>1</sub>    | 43 mm    |
| suitable for colour code | HOLEX NC |
| Jaw height h             | 39.5 mm  |
| Jaw width b              | 124.4 mm |

Data sheet

|                 |           |
|-----------------|-----------|
| for type        | 125       |
| Type of product | Vice jaws |