


 KOMET

**KOMET UniTurn® turning toolholder for stationary use (without boring bar),  
Shank  $\varnothing$  d / Bore  $\varnothing$  d1: 12/4mm**

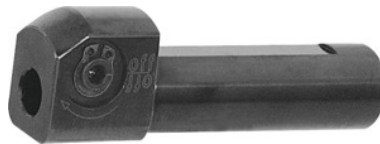

### Order data

Order number	240100 12/4
GTIN	4047109019331
Item class	24S

### Description

**Application:**

For turning and internal grooving on the lathe.

### Technical description

Shank $\varnothing$ d	12 mm
Length a	8 mm
Clamping height b	11 mm
Overall length $L_{tot}$	70 mm
Length $l_2$	45 mm
Bore $\varnothing$ d <sub>1</sub>	4 mm
Through-coolant	yes
Type of product	Cutter holder