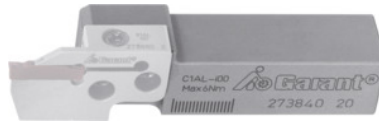


**Garant**
**eco toolholder, right-hand, Shank width b: 25mm**


## Order data

Order number	273840 25
GTIN	4045197517388
Item class	21W

## Description

### Version:

GARANT eco-system toolholders with internal coolant supply to the cutting edge.

### Suitable for:

Blade carriers No. 273880; 273886 and 273890.

### Supplied with:

Including assembly screws.

### Note:

Coolant transfer only possible in conjunction with GARANT eco system toolholders No. **317900** – **319886** and GARANT eco cutter carriers No. **273880** – **273891**. Technology values should be reduced by 30% to 50% depending on the clamping situation and material.

Through-coolant: yes

Overall length L: 96.5 mm

L<sub>2</sub>: 27.5 mm

Screw: 279815 9

## Technical description

Screw	279815 9
Shank width b	25 mm
L <sub>2</sub>	27.5 mm
Overall length L	96.5 mm
Series	Eco
Application type	right-hand

Through-coolant	yes
Type of product	Clamping toolholder

---

## Accessories

Clamping screw	279910
Clamping screw Type 9	279815 9
Torque screwdriver with scale, to take interchangeable blades maximum torque 500 cNm	659906 500
PrecisionBit for Torx®, 1/4 inch E 6.3 Torx® profile TX20	674248 TX20