


## PRYOR

**Interchangeable numeral and letter punch set normal script 0 - 9 and A - Z,  
Character height: 4mm**

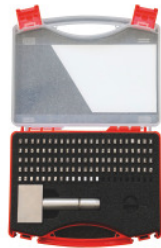

### Order data

Order number	085480 4
GTIN	5022044020306
Item class	08W

### Description

#### Version:

High precision punch holder for quick and efficient marking with **several letters and numbers at the same time.**

#### Application:

For punching into materials (e.g. identification plates, tools, machine parts etc.) with **strengths up to 1200 N/mm<sup>2</sup>.**

#### Supplied with:

100 stamp types  
12 spacers (font height 5 mm: 6 pieces)  
1 pair of tweezers  
1 hexagon L-wrench  
1 holder  
in a plastic box.

#### Spare part:

Individual type punches can be ordered under No. 085481 stating the desired font size / type (e.g. No. 085481 size 3/E).

### Technical description

Number of punch types that can be used	9
Width of punch type	4 mm
Height of punch type	8 mm
Length of punch type	19.05 mm
Character height	4 mm
Length of punch holder	39 mm
Type of product	Hand punch

## Accessories

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/N mm	085481 4/N
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4// mm	085481 4//
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/8 mm	085481 4/8
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4LEER mm	085481 4LEER
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/0 mm	085481 4/0
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/B mm	085481 4/B
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/9 mm	085481 4/9
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/5 mm	085481 4/5
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/M mm	085481 4/M
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/- mm	085481 4/-
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/E mm	085481 4/E

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/H mm	085481 4/H
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/P mm	085481 4/P
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/. mm	085481 4/.
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/7 mm	085481 4/7
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/, mm	085481 4/,
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/S mm	085481 4/S
Steel type holder individual for set No. 085480 suitable for font 4-5 mm	085482 4-5
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/Q mm	085481 4/Q
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/C mm	085481 4/C
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/W mm	085481 4/W
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/1 mm	085481 4/1
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/L mm	085481 4/L
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/4 mm	085481 4/4
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/D mm	085481 4/D
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/Z mm	085481 4/Z
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/3 mm	085481 4/3
Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/U mm	085481 4/U
	085481 4/O

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/O mm

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/I mm

085481 4/I

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/6 mm

085481 4/6

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/J mm

085481 4/J

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/G mm

085481 4/G

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/K mm

085481 4/K

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/X mm

085481 4/X

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/R mm

085481 4/R

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/+ mm

085481 4/+

Interchangeable steel type punches Numbers range 0 – 9 Character height 4 mm

085483 4

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/T mm

085481 4/T

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/Y mm

085481 4/Y

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/2 mm

085481 4/2

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/F mm

085481 4/F

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/V mm

085481 4/V

Steel type punches individually exchangeable, for set No. 085480 Character height / Characters 4/A mm

085481 4/A