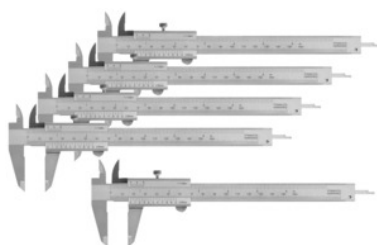


**Calipers Vernier 1/20, Measuring range: 150mm****Order data**

Order number	GG4102 150
GTIN	4069515051323
Item class	GGN

Description**Version:**

Satin chromium plated anti-glare reading parts.

Locking screw at the top.

Supplied with:

Including thread table No. 412180 for caliper back. 5 pcs. analogue caliper No. 410200 150.

Note:

The version for left-handed people can be found under No. 410205 size 150.

Technical description

Calibration	A1
Measuring range	0 - 150 mm
Graduation	1/128 in
Jaw length	40 mm
Depth gauge	rectangular 3.7×1.3
Scale divisions	5 mm
Reversible reading	mm / inch
Measurement deviation E MPE	±0.05 mm

Data sheet

Depth gauge available	yes
Standard	ISO 13385
Graduation	1/20 mm
Packaging	Wallet
Locking	Locking screw at top
Measurement technology	analogue
Material	Stainless steel, INOX
all parts	hardened
Thread table	Calipers table
Type of product	Universal caliper

Suitable products

No Shop URL available for: GG4102 150