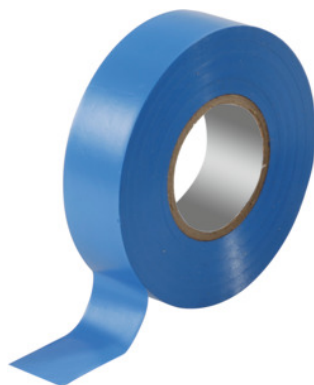


**3M****Insulating tape, 19 mm×25 m, Colour: BLUE**

## Order data

Order number	083654 BLUE
GTIN	4054596615403
Item class	08M

## Description

**Version:**

**3M™ Temflex® 165** is a **general-purpose soft PVC insulating tape**. Flame resistant. Self-extinguishing, good resistance to oil and solvents.

**Application:**

For insulating, binding, securing, and colour marking.

**Note:**

The specified "best before" date for 3M™ products is in relation to compliance with the specified storage guidelines.

## Technical description

Length	25 m
Colour	blue
Width	19 mm
Thickness	0.15 mm
Manufacturer's designation	3M® Temflex® 165

Backing material	PVC film
Stretch capability	200 %
Adhesive strength on steel	0.2 N/mm
temperature-resistant up to	90 °C
Application	Identification
Application	Attaching
Application	Insulating
Application	Binding
Application	Marking
Storage humidity	50 - 60 %
Tensile strength	2 N/mm
Storage temperature	20 - 23 °C
Type of adhesive tape	single-sided
Liner present	no
Product name attribute	19 mm×25 m
Type of product	Adhesive tape