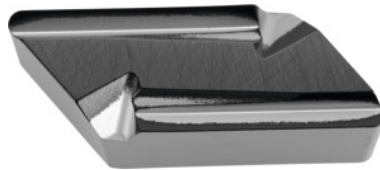


Garant
KNUX 160405L, Grade: HB7120-1

Order data

Order number	251032 HB7120-1
GTIN	4045197819857
Item class	21G

Description

KNUX 160405L HB7120-1 Grade: HB7120-1

Chip breaker: VM

Chip diverter: 2.2 mm

Cutting depth a_p : 0.5 - 5 mm

Feed f : 0.2 - 0.5 mm/rev.

Cutting speed v_c main application: 80 - 260 m/min

Technical description

Main application	M
Chip breaker	VM
Feed f	0.2 - 0.5 mm/rev.
Cutting depth a_p	0.5 - 5 mm
Chip diverter	2.2 mm
Grade	HB7120-1
Cutting conditions	continuous
Cutting speed v_c main application	80 - 260 m/min
Corner radius	0.5 mm
Finishing/roughing assignment	Skrubbearbejdning-sletbearbejdning

Tool material	Carbide
Number of changes/inserts	2
ISO code indexable insert	KNUX 160405L
Type of product	Indexable insert for turning