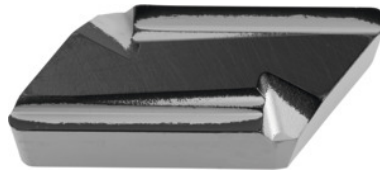


Garant
KNUX 160410R, Grade: HB7120-1

Order data

Order number	251036 HB7120-1
GTIN	4045197819864
Item class	21G

Description

KNUX 160410R HB7120-1 Grade: HB7120-1
 Chip breaker: VM
 Chip diverter: 2.2 mm
 Cutting depth a_p : 0.5 - 5 mm
 Feed f : 0.2 - 0.5 mm/rev.
 Cutting speed v_c main application: 80 - 260 m/min

Technical description

Cutting conditions	continuous
Feed f	0.2 - 0.5 mm/rev.
Chip breaker	VM
Cutting speed v_c main application	80 - 260 m/min
Corner radius	1 mm
Main application	M
Cutting depth a_p	0.5 - 5 mm
Chip diverter	2.2 mm
Grade	HB7120-1
Finishing/roughing assignment	Skrubbearbejdning-sletbearbejdning

Tool material	Carbide
Number of changes/inserts	2
ISO code indexable insert	KNUX 160410R
Type of product	Indexable insert for turning