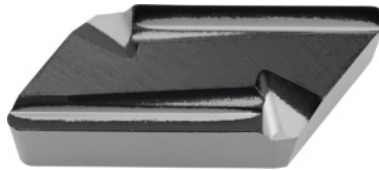


**Garant**
**KNUX 160405R, Grade: HB7140-1**


## Order data

Order number	251030 HB7140-1
GTIN	4045197820532
Item class	21G

## Description

KNUX 160405R HB7140-1 Grade: HB7140-1

Chip breaker: VM

Chip diverter: 2.2 mm

Cutting depth  $a_p$ : 0.5 - 5 mm

Feed  $f$ : 0.2 - 0.5 mm/rev.

Cutting speed  $v_c$  main application: 60 - 230 m/min

## Technical description

Cutting speed $v_c$ main application	60 - 230 m/min
Corner radius	0.5 mm
Feed $f$	0.2 - 0.5 mm/rev.
Cutting conditions	slightly interrupted
Chip diverter	2.2 mm
Main application	M
Cutting depth $a_p$	0.5 - 5 mm
Grade	HB7140-1
Chip breaker	VM
Finishing/roughing assignment	Skrubbearbejdning-sletbearbejdning

Tool material	Carbide
Number of changes/inserts	2
ISO code indexable insert	KNUX 160405R
Type of product	Indexable insert for turning