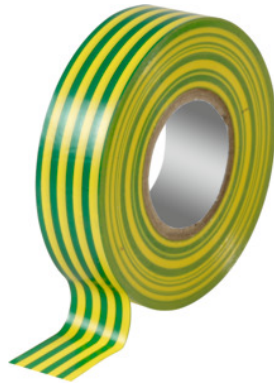


**3M****Insulating tape, 15 mm×10 m, Colour: Y/G**

## Order data

Order number	083652 Y/G
GTIN	4054596657441
Item class	08M

## Description

**Version:**

**3M™ Temflex® 165** is a **general-purpose soft PVC insulating tape**. Flame resistant. Self-extinguishing, good resistance to oil and solvents.

**Application:**

For insulating, binding, securing, and colour marking.

**Note:**

The specified "best before" date for 3M™ products is in relation to compliance with the specified storage guidelines.

## Technical description

Thickness	0.15 mm
Width	15 mm
Colour	yellow-green
Length	10 m
Manufacturer's designation	3M® Temflex® 165

Application	Identification
Application	Insulating
Application	Binding
Application	Marking
Tensile strength	2 N/mm
Liner present	no
Backing material	PVC film
Type of adhesive tape	single-sided
Storage temperature	20 - 23 °C
temperature-resistant up to	90 °C
Storage humidity	50 - 60 %
Adhesive strength on steel	0.2 N/mm
Stretch capability	200 %
Product name attribute	15 mm×10 m
Type of product	Adhesive tape