


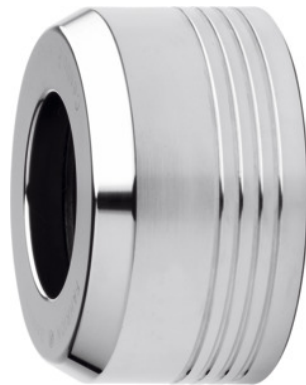

## ER clamping nut CENTRO P Standard, Type CP for ER: 40



### Order data

Order number	309655 40
GTIN	2050001736703
Item class	34F

### Description

#### Version:

**Mini** = all sizes with "M", extremely slim design.

**MiniSlim** = sizes with "MS", extremely super slim design.

**Conical** = all sizes with "C".

**Standard** = all other sizes.

With trapezoidal thread for high clamping forces. Extra long double guidance of the ER clamping nut. ER clamping nuts coated for reduction of **friction**.

ER clamping nut CP, **not suitable for HP sealing rings**.

#### Suitable for:

**FAHRION ER collet chuck CENTRO P.**

#### Optional extras:

Sealing rings No. 309666 – 309668. Clamping wrenches No. 309754 – 309756. HP collets No. 309349 – 309359.

#### Note:

**FAHRION system** ER clamping nuts type CP and sealing rings type HP **do not fit on to other systems!**

Only the nominal size can be clamped (no intermediate range!)

Clamping range: 3 - 26 mm

Overall length L: 31.5 mm

External Ø D: 63 mm

maximum tightening torque: 200 N·m  
Thread: Tr50×1.5

---

## Technical description

Overall length L	31.5 mm
Clamping range	3 - 26 mm
maximum tightening torque	200 N·m
External Ø D	63 mm
Series	Centro P
Thread	Tr50×1.5
Type of product	Clamping nut