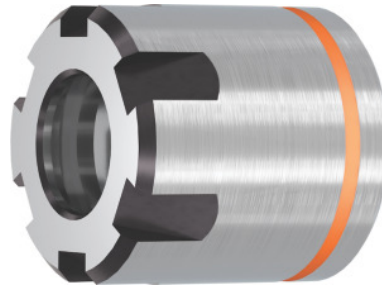


Garant
ER Mini clamping nut for sealing rings, for ER: 25

Order data

Order number	309652 25
GTIN	4045197645739
Item class	31Z

Description
Version:

Small external dimensions, case-hardened and ground on all faces.

· **Case-hardened and ground on all faces.**

Suitable for :

ER collet chuck Mini No. 300650; 300652; 300665; 300685; 305710; 305712; 305715; 300649; 300651; 300661; 300684; 300667; 300669; 305707; 305709; 305717; 305721; 305723.

Machining strategy: HSC

Overall length L: 25 mm

External Ø D: 35 mm

Thread: M30×1

maximum tightening torque: 45 N·m

Technical description

Thread	M30×1
maximum tightening torque	45 N·m
Overall length L	25 mm
for ER	25 mm
External Ø D	35 mm

Standard	DIN 6499
Balance quality G at rotational speed	G 2.5 at 25,000 rpm
Machining strategy	HSC
Type of product	Clamping nut