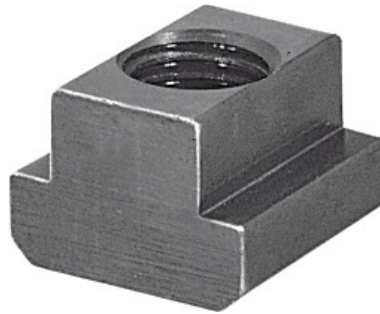


**T-nut, M14, for T-slot nominal size: 16mm****Order data**

| | |
|--------------|---------------|
| Order number | 370550 16 |
| GTIN | 4020772080051 |
| Item class | 35A |

Description**Application:**

For combination with studs or bolts.

Standard:

DIN 508

Material:

Quenched and tempered steel, strength 10.

Note:

Full load-bearing capacity only when threaded for the **entire** nut length.

Technical description

| | |
|---------------------|---------|
| Height k | 9 mm |
| Length | 25 mm |
| Width e | 25 mm |
| Nut height | 18 mm |
| T-slot nominal size | 16 mm |
| Width a | 15.7 mm |

| | |
|-----------------|----------------------|
| Type | 508 |
| Standard | DIN 508 |
| Thread size | M14 |
| with thread | yes |
| Material | Heat-treatable steel |
| Strength class | 10 |
| Type of product | Tee-nut |