


**Kroepelin**  
Längenmesstechnik

## Digital internal quick caliper, Measuring range: 30-50 mm

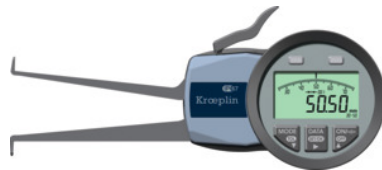

### Order data

Order number	438974 30-50
GTIN	2050001055224
Item class	46Q

### Description

#### Version:

1 fixed and 1 movable arm with carbide spherical contact points. **Digital display of the absolute value.**

By entering **preset values**, variations can be determined against any value.

#### Supplied with:

1 battery No. 081556 size LR3, operating instructions.

#### Optional extras:

Data cable adapter No. 498954 size A2, data cable No. 497440.

Norm: Manufacturer's standard

Reversible reading: mm / inch

Interface: USB interface

Interface: Digimatic interface

IP Index of Protection: IP 67

Measured value saving: Once-off setting of the zero position

Graduations: 0.01 mm

Error limit: 0.03 mm

Repetition accuracy: 0.01 mm

Carbide spherical point  $\varnothing$ : 1 mm

minimum groove width: 1.2 mm

maximum groove depth: 7 mm

### Technical description

maximum groove depth	7 mm
----------------------	------

Gauging force	1.1 - 1.6 N
minimum groove width	1.2 mm
Measuring range	30 - 50 mm
Graduations	0.01 mm
Carbide spherical point Ø	1 mm
maximum contact point length L (measurement depth)	85 mm
Repetition accuracy	0.01 mm
Error limit	0.03 mm
Article no of the battery / rechargeable battery fitted	081561 LR3
Number of batteries contained	1
Norm	Manufacturer's standard
Reversible reading	mm / inch
Interface	USB interface
Interface	Digimatic interface
IP Index of Protection	IP 67
Measured value saving	Once-off setting of the zero position
Measurement technology	digital
Calibration	C7
Type of product	Internal quick calipers

## Services

Calibration External / internal quick caliper	013850
Labelling laser-etched Type	018940
DAkkS calibration External / internal quick caliper	011320

## Accessories

Multi-receiver / USB keyboard interface	498975
Receiver / USB keyboard interface	498965
Connecting cable Type D2	497440 D2

Connecting cable Type D1	497440 D1
Interface adapter Type A2	498954 A2
Alkaline-manganese batteries International size LR3	081556 LR3
Transmitter Type S2	498966 S2
Connecting cable Type USB2	497440 USB2