


Digital external quick caliper with spherical anvils, Measuring range: 0-50mm

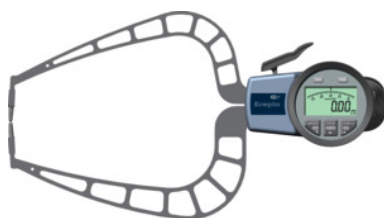

Order data

Order number	438575 0-50
GTIN	2050001743121
Item class	46Q

Description

Version:

1 fixed and 1 movable arm with carbide spherical contact points. **Digital display of the absolute value.**

By entering **preset values**, variations can be determined against any value.

Function:

IP67: Protected against intermittent immersion in water and protected against penetration by dust (dust-tight), also completely protected against touching.

Supplied with:

Supplied with 2 batteries No. 081561 size LR3.

Optional extras:

Data cable adapter No. 498954 size A2, data cable No. 497440.

Technical description

Graduations	0.02 mm
Gauging force	0.9 - 1.2 N
Measurement tip length top Hb	30 mm
Carbide spherical point Ø	3 mm
maximum contact point length L (measurement depth)	167 mm
Measurement tip length bottom Hf	30 mm

Data sheet

Measuring range	0 - 50 mm
Repetition accuracy	0.04 mm
Error limit	0.06 mm
#Number of batteries contained	2
#Article no of the battery / rechargeable battery fitted	081561 LR3
IP Index of Protection	IP 67
Power supply	Battery-powered
Standard	Manufacturer's standard
Reversible reading	mm / inch
Interface	USB interface
Interface	USB interface
Measured value saving	once-off setting of the zero position
Measurement technology	digital
Calibration	C7
Type of product	External quick callipers

Suitable products

<https://www.hoffmann-group.com/GB/en/hom/p/438575-0-50>