


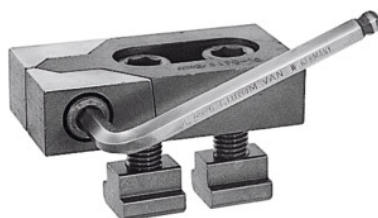

## Pair of low height clamping jaws Bulle with accessories, Slot width a: 12mm



### Order data

Order number	375110 12
GTIN	4020772072957
Item class	35A

### Description

#### Version:

Flat design, no protruding T-bolts. Clamps at any angle to table slot. When the side screw is tightened, the component is securely clamped down on to the table by the wedge effect.

#### Application:

**For lateral clamping of flat plates** directly on the machine table.

#### Material:

Hardened steel, burnished finish.

#### Supplied with:

2 fastening screws, DIN 912, 10.9, T-nuts, and hexagon key L-wrench ISO 2936 C.

#### Note:

Only supplied in pairs!

### Technical description

for clamping screws	M10
Length	80 mm
Height	20 mm
Width	40 mm
Slot width a	12 mm
Type	6490

Type of product

Side clamps