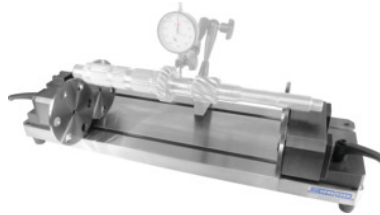


**Bench centre RPGR, for maximum workpiece Ø: 240mm****Order data**

Order number	443230 240
GTIN	2050001698810
Item class	46L

**Description****Version:**

Hardened and ground base plate, bearing body of high-tensile aluminium. Movable scroll plates for high loadings; one of the scroll plates is adjustable for parts with different diameters (up to 60 mm). For correct use an **additional** jointed stand for mounting the dial indicator or lever dial indicator is **required**.

**Application:**

Inspection of axial and radial run-out of rotation parts up to Ø 240 mm.

**Accuracy:**

Concentricity **0.002 mm**.

**Supplied with:**

Base plate with 2 scroll plates; 1 of the scroll plates adjustable for parts with different diameters (without jointed stand and dial indicator).

**Optional extras:**

Jointed stand with T-nut No. 443295.

**Technical description**

Baseplate width	200 mm
Footprint length	600 mm
for maximum workpiece Ø	240 mm
Weight	30 kg

T-slot width H7	10 mm
Type of product	Radial and axial run-out tester

---

## Accessories

Jointed stand with T-nut Throat 200 mm	443295 200
Jointed stand with T-nut Throat 130 mm	443295 130