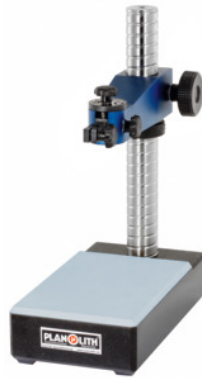


PLANOLITH**Universal precision comparator stand Granite with ceramic coating, Table length: 260mm****Order data**

Order number	442560 260
GTIN	2050001048066
Item class	46H

Description**Version:**

Stand table precision diamond lapped. Extremely rigid and solid structure. Natural granite table of finest quality and hardness.

Column chrome-plated with thread for coarse setting of the cross arm. The rigid measuring arm is equipped with a **parallel fine adjustment**. Holder bore for dial indicators and precision dial indicators \varnothing 8mm.

Flatness $\leq 2 \mu\text{m}$.

With extremely wear-resistant ceramic coating (10 times harder than granite).

Application:

As an particularly accurate and stable comparator stand; can be used for all kinds of inspection procedures, especially for parallelism measurements.

Technical description

Table length	260 mm
Column \varnothing	35 mm
Maximum measuring height	200 mm

Throat	120 mm
Measuring face width	140 mm
Measuring face length	200 mm
Table width	140 mm
Weight	9.5 kg
Standard	DIN 876
Calibration	D1
Type of product	Comparator stand

Services

Calibration Comparator stand maximum table size 400X400 mm	024580 400X400
---	----------------