


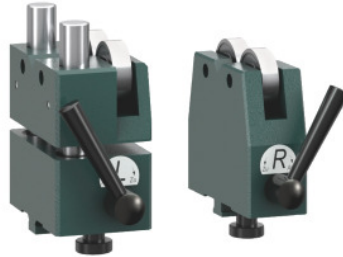

Pair of bench inspection rollers height adjustable, for maximum workpiece \varnothing : 32mm



Order data

Order number	443050 32
GTIN	4030234000435
Item class	46K

Description

Application:

To hold off-centred or over-length parts.
Even for parts with different diameters.

Suitable for:

Bench centre No. 443000 size 50 and 75 / 443210.

Technical description

for maximum workpiece \varnothing	32 mm
Tip height	66 (at d = 10) mm
Width of T-nut h6	10 mm
\varnothing range	2 - 32 mm
maximum load capacity per pair	20 kg
Type of product	Bench inspection roller

