


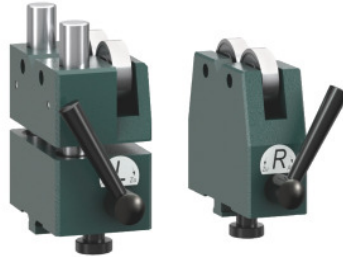

Pair of bench inspection rollers height adjustable, for maximum workpiece \varnothing : 65mm



Order data

Order number	443050 65
GTIN	4030234000428
Item class	46K

Description

Application:

To hold off-centred or over-length parts.
Even for parts with different diameters.

Suitable for:

Bench centre No. 443000 size 100 and 150.

Technical description

Tip height	99 (at d=10) mm
Width of T-nut h6	12 mm
for maximum workpiece \varnothing	65 mm
\varnothing range	2 - 65 mm
maximum load capacity per pair	30 kg
Type of product	Bench inspection roller

