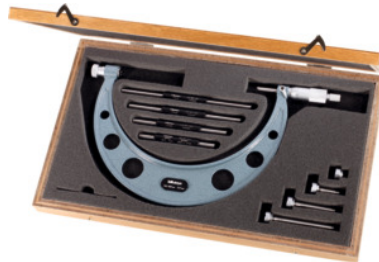


Mitutoyo**Large external micrometer, Measuring range: 400-500mm****Order data**

| | |
|--------------|----------------|
| Order number | 420810 400-500 |
| GTIN | 4946368215150 |
| Item class | 44A |

Description**Version:**

Hardened and ground measuring spindle and measuring faces; locked by locking lever. With ratchet. Glare-free satin chrome-plated barrel with 1/50 scale and cleanly engraved black graduations and numerals.

4 easily interchangeable anvils give a measurement range of 100 mm per size.

Technical description

| | |
|--------------------------------|--------------|
| Barrel Ø | 21 mm |
| Weight | 6.7 kg |
| Number of measuring tips | 4 |
| Spindle Ø | 8 mm |
| Scale divisions | 0.01 mm |
| Spindle travel | 25 mm |
| Number of micrometer standards | 4 |
| Micrometer barrel graduations | 1/50 mm |
| Measuring range | 400 - 500 mm |

| | |
|------------------------|--------------------------|
| Calibration | S3 |
| Error limit | 3 μm |
| Standard | Works standard |
| Measurement technology | analogue |
| Packaging | sturdy box |
| Type of product | External tube micrometer |

Services

| | |
|--|----------------|
| Calibration External micrometers with extensions Measuring range 400-500 mm | 020450 400-500 |
|--|----------------|