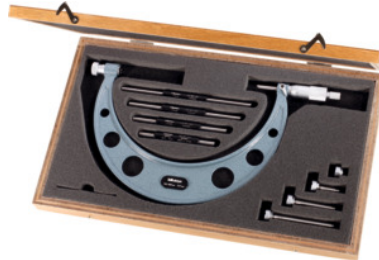


Mitutoyo**Large external micrometer, Measuring range: 700-800mm****Order data**

Order number	420810 700-800
GTIN	2050001059994
Item class	44A

Description**Version:**

Hardened and ground measuring spindle and measuring faces; locked by locking lever. With ratchet. Glare-free satin chrome-plated barrel with 1/50 scale and cleanly engraved black graduations and numerals.

4 easily interchangeable anvils give a measurement range of 100 mm per size.

Technical description

Barrel Ø	21 mm
Number of micrometer standards	4
Number of measuring tips	4
Spindle Ø	8 mm
Scale divisions	0.01 mm
Micrometer barrel graduations	1/50 mm
Spindle travel	25 mm
Weight	14.8 kg
Measuring range	700 - 800 mm

Calibration	S3
Error limit	3 μ m
Standard	Manufacturer's standard
Measurement technology	analogue
Packaging	sturdy box
Type of product	External tube micrometer

Services

Calibration External micrometers with extensions Measuring range 700-800 mm	020450 700-800
--	----------------