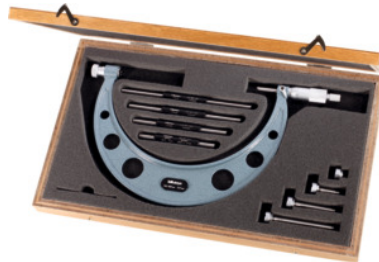


**Mitutoyo****Large external micrometer, Measuring range: 100-200mm****Order data**

Order number	420810 100-200
GTIN	4946368215129
Item class	44A

**Description****Version:**

Hardened and ground measuring spindle and measuring faces; locked by locking lever. With ratchet. Glare-free satin chrome-plated barrel with 1/50 scale and cleanly engraved black graduations and numerals.

**4 easily interchangeable anvils give a measurement range of 100 mm per size.**

**Technical description**

Number of micrometer standards	4
Weight	1.8 kg
Barrel Ø	18 mm
Spindle Ø	6.35 mm
Micrometer barrel graduations	1/50 mm
Measuring range	100 - 200 mm
Spindle travel	25 mm
Number of measuring tips	4
Scale divisions	0.01 mm

Calibration	S3
Error limit	3 µm
Standard	Works standard
Measurement technology	analogue
Packaging	sturdy box
Type of product	External tube micrometer

### Services

Calibration External micrometers with extensions Measuring range 100-200 mm	020450 100-200
--	----------------