


Mitutoyo

Large external micrometer, Measuring range: 200-300mm

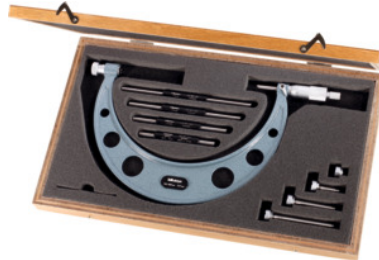

Order data

Order number	420810 200-300
GTIN	4946368215136
Item class	44A

Description

Version:

Hardened and ground measuring spindle and measuring faces; locked by locking lever. With ratchet. Glare-free satin chrome-plated barrel with 1/50 scale and cleanly engraved black graduations and numerals.

4 easily interchangeable anvils give a measurement range of 100 mm per size.

Technical description

Barrel Ø	18 mm
Measuring range	200 - 300 mm
Spindle Ø	6.35 mm
Scale divisions	0.01 mm
Spindle travel	25 mm
Weight	3.4 kg
Number of measuring tips	4
Number of micrometer standards	4
Micrometer barrel graduations	1/50 mm

Calibration	S3
Error limit	3 μm
Standard	Works standard
Measurement technology	analogue
Packaging	sturdy box
Type of product	External tube micrometer

Services

Calibration External micrometers with extensions Measuring range 200-300 mm	020450 200-300
--	----------------