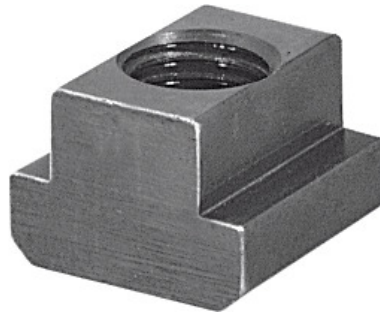


**T-nut with threaded shank, T-slot nominal size: 16mm****Order data**

Order number	375315 16
GTIN	2050002047013
Item class	35A

Description**Application:**

For combination with studs or bolts.

Standard:

DIN 508

Material:

Quenched and tempered steel, strength 10.

Note:

Full load-bearing capacity only when threaded for the **entire** nut length.

Thread: M14

Nut height: 18 mm

Width a: 15.7 mm

Width e: 25 mm

Height k: 9 mm

Technical description

T-slot nominal size	16 mm
Thread	M14
Width a	15.7 mm

Nut height	18 mm
Width e	25 mm
Height k	9 mm
Type	508
Type of product	Tee-nut

Accessories

T-nut T-slot nominal size 16 mm	370550 16
---------------------------------	-----------