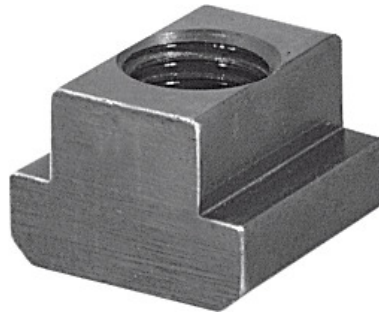


**T-nut with threaded shank, T-slot nominal size: 20mm****Order data**

Order number	375315 20
GTIN	4020772080075
Item class	35A

Description**Application:**

For combination with studs or bolts.

Standard:

DIN 508

Material:

Quenched and tempered steel, strength 10.

Note:

Full load-bearing capacity only when threaded for the **entire** nut length.

Technical description

Thread	M18
Nut height	24 mm
T-slot nominal size	20 mm
Width a	19.7 mm
Width e	32 mm
Height k	12 mm

Type	508
Type of product	Tee-nut