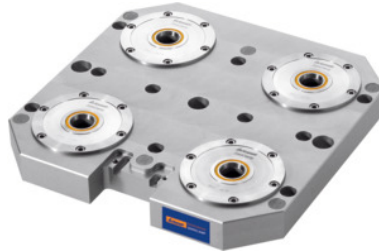


**Garant****ZeroClamp base plate, Type: 10008****Order data**

Order number	360012 10008
GTIN	4045197377012
Item class	310

**Description****Version:**

All bores for T-slot pitches of **63, 100, 125 mm**.

Centre bore  $\varnothing$  25 H7 to receive a centring set. The zero point clamping of the GARANT ZeroClamp system is an important function for modern production systems, especially in automated production. Thanks to a special contact interface, it ensures precise and reliable zero point repetition accuracy. The pneumatic clamping force of the system holds workpieces securely in the desired position, making it possible to change workpieces quickly and accurately without repositioning. This reduces the set-up effort and increases productivity. The zero point clamping of the GARANT ZeroClamp system is indispensable for efficient production processes. Find out more about the innovative technology from GARANT ZeroClamp and optimise your production.

**Application:**

For vertical/horizontal machines.

**Material:**

**Base plate** of high-tensile aluminium, surface treated.

All components of the clamping pot of stainless or corrosion-resistant steel.

**Optional extras:**

Clamping stud No. 360025,

Connection block No. 360017 size 12808 / 12805.

**Note:**

Base plates with clamping pot dia. 138 mm are also available with self-locking clamping pots on request.

## Technical description

Height H	44 mm
Width B	366 mm
Clamping pot $\varnothing$	120 mm
Type	10008
Length A	366 mm
Number of clamping pots	4
Pitch S	200 mm
Series	ZeroClamp
Type of product	Baseplate

## Accessories

ZeroClamp clamping stud with internal thread Type 18M16	360025 18M16
ZeroClamp cover plate for base plate Type 11355	360013 11355
ZeroClamp clamping stud with internal thread Type 18M16/138	360025 18M16/138
ZeroClamp clamping stud with internal thread Type 18M12	360025 18M12
ZeroClamp clamping stud with internal thread Type 14M12/90	360025 14M12/90
ZeroClamp clamping stud with internal thread Type 12M10/138	360025 12M10/138
ZeroClamp clamping stud with internal thread Type 18M12/138	360025 18M12/138
ZeroClamp clamping stud with internal thread Type 16M8	360025 16M8
ZeroClamp clamping stud with internal thread Type 12M10/90	360025 12M10/90
ZeroClamp clamping stud with internal thread Type 25M10	360025 25M10
	360025 25M16/138

ZeroClamp clamping stud with internal thread Type  
25M16/138

ZeroClamp clamping stud with internal thread Type 12M10	360025 12M10
---	--------------

ZeroClamp connection block Type 12805	360017 12805
---------------------------------------	--------------

ZeroClamp clamping stud with internal thread Type 25M10/138	360025 25M10/138
--	------------------

ZeroClamp connection block Type 12808	360017 12808
---------------------------------------	--------------

ZeroClamp clamping stud with internal thread Type 16M10	360025 16M10
---	--------------