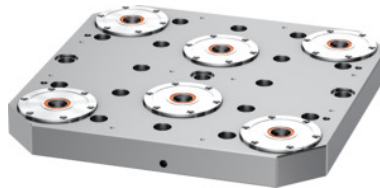


Garant
**ZeroClamp 6-pot base plate or clamping towers for horizontal machines,
Type: 10243**

Order data

Order number	360022 10243
GTIN	
Item class	310

Description
Version:

Clamping pot \varnothing **120 mm**. The zero point clamping of the GARANT ZeroClamp system is an important function for modern production systems, especially in automated production. Thanks to a special contact interface, it ensures precise and reliable zero point repetition accuracy. The pneumatic clamping force of the system holds workpieces securely in the desired position, making it possible to change workpieces quickly and accurately without repositioning. This reduces the set-up effort and increases productivity. The zero point clamping of the GARANT ZeroClamp system is indispensable for efficient production processes. Find out more about the innovative technology from GARANT ZeroClamp and optimise your production.

Base plate with 6 clamping pots, to accept the clamping towers. Drilled for T-slots at 100 mm intervals, centre hole \varnothing 25H7 to accept a centring set.

Optional extras:

Clamping stud No. 360025.

Technical description

Pitch S	350 (4x), 200 (2x) mm
Type	10243
Number of clamping pots	6
Series	ZeroClamp

Indexing hole available	no
Type of product	Baseplate

Accessories

ZeroClamp clamping stud with internal thread Type 18M12/138	360025 18M12/138
ZeroClamp clamping stud with internal thread Type 12M10/90	360025 12M10/90
ZeroClamp clamping stud with internal thread Type 12M10	360025 12M10
ZeroClamp clamping stud with internal thread Type 18M16/138	360025 18M16/138
ZeroClamp clamping stud with internal thread Type 18M12	360025 18M12
ZeroClamp clamping stud with internal thread Type 16M8	360025 16M8
ZeroClamp clamping stud with internal thread Type 25M10	360025 25M10
ZeroClamp clamping stud with internal thread Type 12M10/138	360025 12M10/138
ZeroClamp clamping stud with internal thread Type 16M10	360025 16M10
ZeroClamp clamping stud with internal thread Type 25M16/138	360025 25M16/138
ZeroClamp clamping stud with internal thread Type 25M10/138	360025 25M10/138
ZeroClamp clamping stud with internal thread Type 18M16	360025 18M16
ZeroClamp clamping stud with internal thread Type 14M12/90	360025 14M12/90