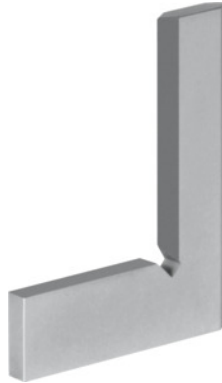


Garant

Bevel edge square, flat version stainless, accuracy class 00, Stock length: 50X40mm

**Order data**

| | |
|--------------|---------------|
| Order number | 450010 50X40 |
| GTIN | 4045197443939 |
| Item class | 41G |

Description**Version:**

Very high accuracy. With two bevelled straight edges on the long blade.
Through hardened and stress-relieved. Test faces ground and lapped, other faces ground.

Application:

For inspection work using the light gap principle.

Technical description

| | |
|-----------------------|-----------------------|
| Shank cross-section | 13×4 mm |
| Length of long arm | 50 mm |
| Length of short arm | 40 mm |
| Right angle tolerance | 0.003 mm |
| Standard | DIN 875/00 |
| Material | Stainless steel, INOX |

| | |
|-----------------|--------------|
| all parts | hardened |
| Packaging | sturdy box |
| Calibration | F1 |
| Type of product | Bevel square |