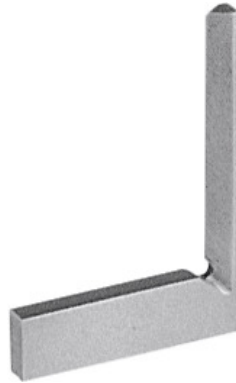


Garant

**Die maker's square hardened stainless, accuracy class 00, Stock length:
40X28mm**

**Order data**

Order number	450040 40X28
GTIN	4045197444042
Item class	41G

Description**Version:**

Highest accuracy. Bevelled edge on long narrow blade. High-tensile steel, fully hardened and stress-relieved. Test faces ground and lapped. All other faces ground.

Application:

For jig and tool making.

Technical description

Length of short arm	28 mm
Right angle tolerance	0.003 mm
Cross-section of short arm	4x3.5 mm
Length of long arm	40 mm
Standard	DIN 875/00
Material	Stainless steel, INOX

all parts	hardened
Packaging	sturdy box
Calibration	F1
Type of product	Try squares

Services

CalibrationStock, try, and bevel edge squares maximum arm length 100 mm	025000 100
---	------------