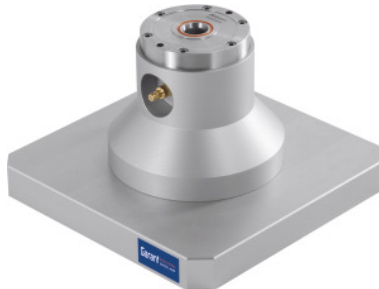


**Garant****ZeroClamp extension base with 1 clamping point, Type: 12281****Order data**

Order number	360030 12281
GTIN	4045197415530
Item class	310

**Description****Version:**

Clamping pot  $\varnothing$  **120 mm**, indexed. The zero point clamping of the GARANT ZeroClamp system is an important function for modern production systems, especially in automated production. Thanks to a special contact interface, it ensures precise and reliable zero point repetition accuracy. The pneumatic clamping force of the system holds workpieces securely in the desired position, making it possible to change workpieces quickly and accurately without repositioning. This reduces the set-up effort and increases productivity. The zero point clamping of the GARANT ZeroClamp system is indispensable for efficient production processes. Find out more about the innovative technology from GARANT ZeroClamp and optimise your production.

**Suitable for:**

For base plates with pitch 200.

**Supplied with:**

Including coupling plug and clamping stud No. 360025 size 18M16.

**Optional extras:**

Quick-release coupling No. 360019 size 10241 and size 1003.

**Technical description**

Type	12281
Width B	330 mm

Installed height H	200 mm
Number of clamping studs	4
Series	ZeroClamp
Connection thread	1/4 in
Type of product	Extension base

---

## Accessories

ZeroClamp quick-release coupling Type 10003	360019 10003
ZeroClamp quick-release coupling Type 10241	360019 10241